



Фітинги Мод. FD7510

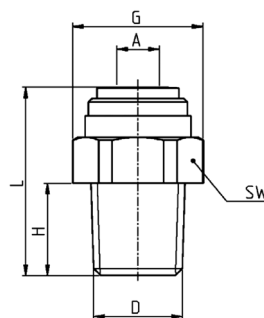

РОЗМІРИ

Мод.	A	D	G	H	L	SW	Вага (г)
FD7510 4-1/8	4	R1/8	18.5	9.1	26	17	4.1
FD7510 6-1/8	6	R1/8	18.5	9.1	26.2	17	3.9
FD7510 6-1/4	6	R1/4	18.5	13.1	26.7	17	4.2
FD7510 6-3/8	6	R3/8	21	13.5	26.6	19	5.9
FD7510 8-1/8	8	R1/8	21	9.1	28.1	19	5.2
FD7510 8-1/4	8	R1/4	21	13.1	30.6	19	5.8
FD7510 8-3/8	8	R3/8	21	13.5	27	19	5.7
FD7510 10-3/8	10	R3/8	23.2	13.5	28.8	21	6.7
FD7510 10-1/2	10	R1/2	24.4	16.3	32.1	22	9.6
FD7510 12-3/8	12	R3/8	26.5	13.5	32.2	24	8.9
FD7510 12-1/2	12	R1/2	26.5	16.3	34.3	24	11

Фітинги Мод. FD7512

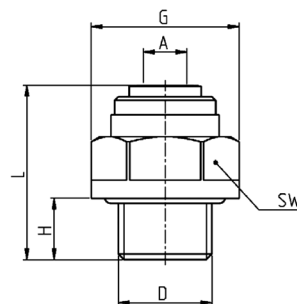

РОЗМІРИ

Мод.	A	D	G	H	L	SW	Вага (г)
FD7512 4-1/8	4	G1/8	16.6	6	21.9	15	3.3
FD7512 4-1/4	4	G1/4	20.5	8.5	23.9	18	4.9
FD7512 6-1/8	6	G1/8	16.6	6	24.1	15	3.3
FD7512 6-1/4	6	G1/4	20.5	8.5	24.1	18	4.8
FD7512 8-1/8	8	G1/8	18.5	6	27	17	5.2
FD7512 8-1/4	8	G1/4	20.5	8.5	28.5	18	6.1
FD7512 8-3/8	8	G3/8	24	9	26.5	21	7
FD7512 8-1/2	8	G1/2	28.5	12.5	29.5	26	11.9
FD7512 10-1/4	10	G1/4	21.1	8.5	30.8	19	7.2
FD7512 10-3/8	10	G3/8	24.2	9	26.3	21	7
FD7512 10-1/2	10	G1/2	28.5	12.5	29.8	26	11.3
FD7512 12-3/8	12	G3/8	27	9	34.2	24	11.6
FD7512 12-1/2	12	G1/2	28.5	12.5	32.7	26	12.4