



Фітинги Мод. FD7463

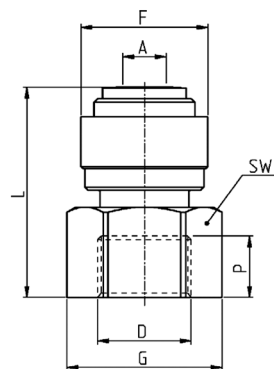

РОЗМІРИ									
Мод.	A	D	F	G	L	P	SW	Bara (r)	
FD7463 4-1/8	4	G1/8	17.6	19.2	26.9	6	17	6.6	
FD7463 6-1/8	6	G1/8	17.6	19.2	27.1	6	17	6.1	
FD7463 6-1/4	6	G1/4	17.6	21.5	29.1	8.5	19	7	
FD7463 6-3/8	6	G3/8	17.6	27.3	30.6	9	24	9.9	
FD7463 8-1/8	8	G1/8	17.6	19.2	27.5	6	17	6	
FD7463 8-1/4	8	G1/4	17.6	21.5	29.5	8.5	19	6.7	
FD7463 8-3/8	8	G3/8	17.6	27.3	31	9	24	9.7	
FD7463 8-1/2	8	G1/2	20	30	38	12.5	27	13.8	
FD7463 8-3/4	8	G3/4	20	41.6	36.6	10	36.7	39.2	
FD7463 10-1/4	10	G1/4	23	21.5	34.5	8.5	19	10.8	
FD7463 10-3/8	10	G3/8	23	27.3	37	9	24	13.7	
FD7463 10-1/2	10	G1/2	20	30	38.3	12.5	27	13.3	
FD7463 10-3/4	10	G3/4	20	41.6	36.9	10	36.7	38.6	
FD7463 12-1/4	12	G1/4	23	21.5	35.2	8.5	19	10.3	
FD7463 12-3/8	12	G3/8	23	27.3	37.7	9	24	13	
FD7463 12-1/2	12	G1/2	23	30	41.7	12.5	27	15.4	

Фітинги Мод. FD7522

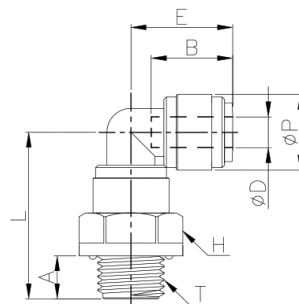

РОЗМІРИ							
Мод.	ØP	A	B	E	H	L	Bara (r)
FD7522 4-1/8	13,2	6,0	14,7	17,9	15,0	28,5	6,0
FD7522 4-1/4	13,2	8,5	14,7	17,9	18,0	31,0	7,7
FD7522 6-1/8	15,0	6,0	16,1	20,1	17,0	30,5	7,7
FD7522 6-1/4	15,0	8,5	16,1	20,1	18,0	33,0	8,7
FD7522 8-1/8	17,6	6,0	17,5	21,9	18,0	31,9	10,4
FD7522 8-1/4	17,6	8,5	17,5	21,9	18,0	34,4	11,0
FD7522 8-3/8	17,6	9,0	17,5	21,9	22,0	34,9	12,8
FD7522 10-1/4	20,0	8,5	20,1	25,8	22,0	38,0	15,4
FD7522 10-3/8	20,0	9,0	20,1	25,8	22,0	38,5	15,8
FD7522 10-1/2	20,0	12,5	20,1	25,8	26,0	42,0	19,1
FD7522 12-3/8	23,0	9,0	24,7	31,7	26,0	43,7	23,2
FD7522 12-1/2	23,0	12,5	14,7	31,7	26,0	47,2	25,2